

KEY
PRODUCTS
FOR YOUR
INDUSTRY

Top Consumables for your Industry

Discover these key daily lab consumables, including tubes, bottles, vials, pipettes, deep-well microplates, tips, syringes and petri dishes



fisherbrand

Conical Polypropylene Centrifuge Tubes

Imprinted clear black graduations ensure accurate readings

- Nonpyrogenic
- Conical bottoms
- Large labelling area
- Choice of plug-seal or flat-top closures
- Sterile and non-sterile styles
- With black graduations and white marking area
- 15mL tubes are graduated in 0.5mL subdivisions from 2 to 14.5mL
- 50mL tubes are graduated in 5mL increments from 5 to 50mL

Cat. No	Description	Pack qty
11512303	Conical Polypropylene Centrifuge Tubes, 50mL	500

Buy Now

Find it at: eu.fishersci.com/go/industryconsumable

 **fisher scientific**
part of Thermo Fisher Scientific



Microcentrifuge Tubes with Locking Snap Cap

Polypropylene microcentrifuge tubes are DNase/RNase and pyrogen-free

- DNase/RNase and pyrogen free
- Available in both sterile and non-sterile options
- Autoclavable and withstand temperatures to -86°C
- Graduated tubes available in three sizes - 0.5mL, 1.5mL and 2.0mL

Cat. No	Description	Pack qty
15432545	Microcentrifuge Tubes with Locking Snap Cap, 1.5mL	500

[Buy Now](#)



Reusable Glass Media Bottles with Cap

Feature clear (natural), drip-free, replaceable polypropylene pour ring

- Permanent white enamel marking spot
- GL 45 screw thread
- Linerless
- Autoclavable (to 140°C)
- Borosilicate glass
- Polypropylene cap

Cat. No	Description	Pack qty
15446113	Reusable Glass Media Bottles with Cap, 100mL	10

[Buy Now](#)



High Temperature Glass Media Bottles with Red Cap

Feature clear (natural), drip-free, replaceable polypropylene pour ring

- Permanent white enamel marking spot
- GL 45 screw thread
- Silicone/PTFE 23 closure liner
- Autoclavable
- Borosilicate glass
- TP 220 cap
- Withstands up to 200°C

Cat. No	Description	Pack qty
15816861	High Temperature Glass Media Bottles with Red Cap, 100mL	10

[Buy Now](#)

fisherbrand

Clear Soda Lime Glass Bottles with Fitted Closure



Soda lime glass bottles with a fitted 28mm closure. Clear glass ideal for storage or handling of media and other solutions.

- Tamper evident vistop closure with polycarbonate liner
- ISO certified
- Clear soda lime glass

Cat. No	Description	Pack qty
12840904	Clear Soda Lime Bottle with Closure, 250mL	60

Buy Now

fisherbrand

Short Thread Glass Vials, Wide Opening, Clear



Universally compatible on almost all autosamplers.

- 9mm
- Short thread
- Glass
- Wide opening
- Clear

Cat. No	Description	Pack qty
11575884	9mm Short Thread Glass Vial, Wide Opening, Clear, 1.5mL	100

Buy Now

fisherbrand

Screw Neck Vials, 13-425 Thread, Glass, 4mL



Ideal for storage purposes when used with closed top screw seals.

- Any combination 28 of these 4mL ND13 vials with one of our 13mm PP screw-top seals can be obtained as a 2-in-1 kit
- For storage purposes also available with closed top screw seals

Cat. No	Description	Pack qty
10571013	Screw Neck Vial, 13-425 Thread, Glass, 4mL	100

Buy Now

fisherbrand

Borosilicate Glass Scintillation Vials, with White Polypropylene Caps



Use these general purpose vials with all common counters. Fisherbrand™ 20mL borosilicate glass scintillation vials with white polypropylene caps feature potassium-free glass composition which provides consistently low activity counts and excellent light transmission.

- Caps fit GPI 22-400 thread finish and are suitable for marking

Cat. No	Description	Pack qty
12383317	Borosilicate Glass Scintillation Vials, with White Polypropylene Caps, 20mL	500

[Buy Now](#)



fisherbrand

Glass Shell Vials

Recommended for HPLC usage

- Shell vials and the appropriate plugs can also be supplied as a 2-in-1 kit
- Handy and inexpensive vial/closure combination for uncritical analyses

Cat. No	Description	Pack qty
11501374	Glass Shell Vial, 1.4mL	100

[Buy Now](#)



fisherbrand

HDPE Wide-Mouth Bottles

Supplied with polypropylene screw caps

- Higher temperature-use rating than LDPE: up to 120°C (248°F) for short periods and 110°C (230°F) for continuous use
- Brittleness temperature at -100°C (-148°F)
- Bottles may be radiation, EtO or chemically sterilised
- Not autoclavable

Cat. No	Description	Pack qty
10062439	Leakproof HDPE Wide-Mouth Bottles, 250mL	12

[Buy Now](#)

fisherbrand



Wide-Mouth Field Sample Bottles

Bulk-packaged for convenient liquid sampling, transport and storage

- Excellent chemical resistance
- Rigid and translucent
- HDPE with polypropylene screw caps

Cat. No	Description	Pack qty
11917974	Wide-Mouth Field Sample Bottles, 125mL	500

Buy Now

fisherbrand



Easy-Squeeze Wash Bottles

Easy to fill and ready to use

- Wide mouth
- Translucent and sputter-free
- With easy-to-read color-coded silk-screened labels
- Tips can be cut back to increase flow
- When not in use, bottles relieve internal pressure without dripping

Cat. No	Description	Pack qty
11745233	Easy-Squeeze Wash Bottles 'Acetone'	6

Buy Now

fisherbrand

Soda Lime Glass Pasteur Pipettes

General purpose Pasteur pipettes ideal for a variety of lab applications.

- Soda lime glass
- Supplied in packs of 1,000

Cat. No	Description	Pack qty
11546963	Soda Lime Glass Pasteur Pipette, 150mm	1000

Buy Now



fisherbrand

Sterile Polystyrene Disposable Serological Pipettes with Magnifier Stripe

These pipettes have improved optical clarity — high-contrast black markings make volumes easier to read

- Colour-coded magnifier stripe runs lengthwise along pipette, making meniscus obvious at arm's length — reducing reading errors
- Sterile and nonwetable
- Offer a tolerance of $\pm 2\%$ at full volume and have plug-in mouth end
- 1, 2, 5, 10, 25 and 50mL pipettes have ascending and descending graduations
- Improved tip design on 25 and 50mL pipettes increases the effect of surface tension to minimise dripping
- Colour-coding on each pipette and on inner bags for multipacks make it easy to spot the size needed

Cat. No	Description	Pack qty
11839660	Sterile Polystyrene Disposable Serological Pipettes with Magnifier Stripe, 10mL	200

[Buy Now](#)



fisherbrand

Non-Sterile Transfer Pipettes, Transparent LDPE

Prevent cross contamination. Fisherbrand™ transfer pipettes are made of shatterproof, flexible LDPE and are designed as an alternative to glass Pasteur pipettes.

- Built-in bulb eliminates the need for plugging, packaging and autoclaving
- Flexible stem bends to sample from narrow or small tubes
- Low affinity surface reduces loss of cells and valuable proteins due to binding

Cat. No	Description	Pack qty
13439108	Non-sterile Transfer Pipettes, Transparent LDPE, 3mL	500

[Buy Now](#)

fisherbrand

Maxi Pipettor Tips

Universal fit for large volume pipettors

- Designed for use when transferring large sample volumes
- Advanced moulding technology ensure tips are straight
- Alternative option to serological pipettes
- Non-sterile; certified by independent laboratory to be RNase, DNase, DNA and pyrogen-free



Cat. No	Description	Pack qty
11957754	Maxi pipettor tips, 10mL	100

[Buy Now](#)

fisherbrand

Beveled Pipettor Tips with graduations

Offering a full line of universal fit beveled pipettor tips

- Flush-fit Inserts sit flush with rack, allowing easy multichannel pipetting
- Notched clasp props lid open for autoclave venting
- Sure Stack lid rim prevents racks from sliding around when stacked and carted around a lab
- Safe-Lock latch allows for one-handed open and closing ability and won't pop open when dropped



Cat. No	Description	Pack qty
11963446	Beveled Pipette Tips, 1-200µL, with graduations	960

[Buy Now](#)

Fisher Scientific provides solutions for all

Industry

You will find lab products for

- Food and Beverage
- Environment
- PFM, Chemical and Cosmetic
- Core Industries and Automotive



fisherbrand

Polypropylene Deep-Well Microplates



Ideal for storage because of the low-binding characteristics of polypropylene

- Accommodate even larger working volumes; up to 1.0 mL or 2.0 mL storage volume per well
- Proteins and DNA will not adhere to PP, allowing for complete sample recovery
- Natural colour
- Non-sterile and sterile options available

Cat. No	Description	Pack qty
13545450	Polypropylene Microplates, 2mL	60

[Buy Now](#)

fisherbrand

Non-Sterile PTFE Syringe Filters



Used for filtration of protein solutions.

- Perfect for daily routine analysis
- Membrane is made of PTFE material
- Low protein binding
- Hydrophilic membrane
- Offers medium chemical resistance


Cat. No	Description	Pack qty
15101499	Non-sterile PTFE Syringe Filters, 0.45µm	50

[Buy Now](#)

Help & Support Center
Fisher Scientific website How-To Videos & FAQs

[Explore Now >](#)

fisher scientific

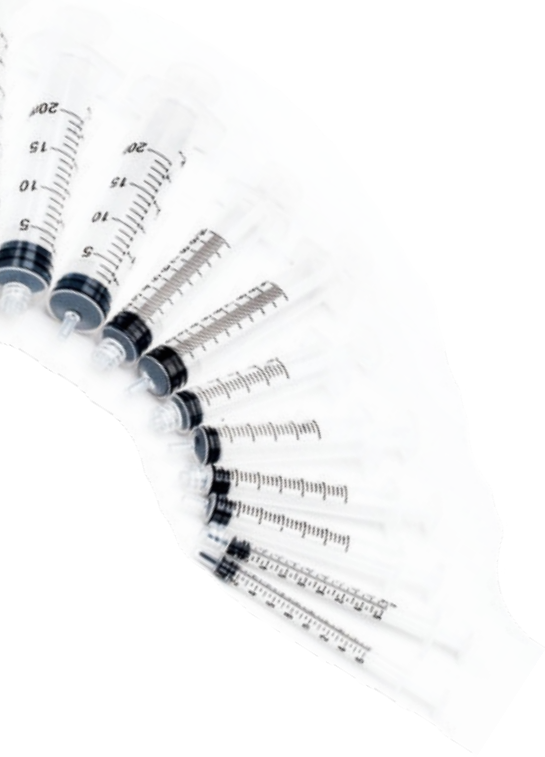

fisherbrand

Sterile Syringes for Single Use

Manual syringe without needle for research purposes only. Suitable for use with syringe filters

- Sterilised by gamma irradiation
- Individually wrapped in a paper/plastic blister pack
- Slip tip or Luer Lock

Cat. No	Description	Pack qty
15879152	Sterile Syringes for Single Use, 10mL Luer Lock	100

Buy Now

fisherbrand

Disposable PES Filter Units

Increase cell culture sample protection with these Fisherbrand sterile disposable vacuum filter units with PES membranes.

- PES membrane is low protein binding to maintain protein balance
- PES membrane has low extractables to maintain media purity
- Upper chamber of filter units is clearly marked with pore size, membrane type, catalogue number, lot number and expiration date
- Non-pyrogenic and non-cytotoxic
- Gamma radiation-sterilised and individually bagged for a five-year sterile shelf life
- 0.2µm units for sterile filtration
- 0.45µm units for fluid clarification and particle removal

Cat. No	Description	Pack qty
15933307	Disposable PES Filter Units, 0.20µm, 1000mL	12

Buy Now



fisherbrand

Squat Form Beakers

Constructed of borosilicate glass. Fisherbrand™ squat form beakers are graduated and come in a large range of capacities.

- With spout
- ISO 3819 DIN 12331
- Marking area

Cat. No	Description	Pack qty
15409083	Squat Form Beakers, 250mL	10

[Buy Now](#)



fisherbrand

Borosilicate Glass Heavy-Duty Low-Form Beakers

Spout designed for optimum performance

- Thick uniform walls
- Evenly tooled top rim with extra wall thickness
- Durable matte finish marking area
- White graduated scale

Cat. No	Description	Pack qty
16505840	Reusable Glass Heavy-Duty Low-Form Beakers, 250mL	12

[Buy Now](#)



Set Your Lab in Motion

Maximise your time and budget while getting the supplies you need



fisherbrand

Polypropylene Clear Autoclave Bags

Designed to be strong, pliable, lean and puncture resistant. Fisherbrand™ polypropylene clear autoclave bags withstand high temperatures for autoclaving.

- For high temperature sterilisation (134°C) to a maximum of 140°C
- 40µm thickness
- High temperature polypropylene bags for the decontamination and inactivation of particularly resistant biological waste
- For safe disposal of biohazard waste

Cat. No	Description	Pack qty
16247971	Polypropylene Autoclave Bags	100

[Buy Now](#)



fisherbrand

Polystyrene Petri Dishes

Polystyrene petri dishes are perfect for microbial or cell culture applications.

- Vented or non-vented options
- Perfect for a range of general purpose applications

Cat. No	Description	Pack qty
12654785	Polystyrene Petri Dishes, 90mm, Single Vent	600

[Buy Now](#)

Download the Lab Equipment & Instrumentation Brochure for our best prices



KEY PRODUCTS FOR YOUR INDUSTRY

Lab Equipment & Instrumentation for your Industry

Discover key items for daily lab analysis from temperature control to cold storage, including balances, hotplates and stirrers, and electrochemistry

Valid until 31 December 2020

BINDER
Best conditions for your success

Model VD 23 Vacuum Drying Chamber for Non-Flammable Solvents, 23L

Temperature Range: Ambient +15°C to 200°C;
Light: No Lighting.

- Patented expansion shelf technology ensures optimal heat transfer
- Direct heat transfer through large thermal conducting plates
- Coordinated modular system with vacuum pump and vacuum module
- Shelves easy to position
- Inner chamber of oven easy to clean

Enter promotion code 14638* to access the promotional prices.

Find it at:
<https://www.fishersci.co.uk/gb/en/catalog/featured/90234015.html>

fisher scientific
part of Thermo Fisher Scientific

BEST PRICE

15632186

Download the Brochure

Contact us today:

Austria: fishersci.at **Belgium:** fishersci.be **Denmark:** fishersci.dk
Germany: fishersci.de **Ireland:** fishersci.ie **Italy:** fishersci.it
Finland: fishersci.fi **France:** fishersci.fr **Netherlands:** fishersci.nl
Norway: fishersci.no **Portugal:** fishersci.pt **Spain:** fishersci.es
Sweden: fishersci.se **Switzerland:** fishersci.ch **UK:** fishersci.co.uk

© 2020 Thermo Fisher Scientific Inc. All rights reserved.
Trademarks used are owned as indicated at fishersci.com/trademarks.

fisher scientific
part of Thermo Fisher Scientific